



HSTPCL06256IPK25, Heat Shrink Tubing, Thin Wall, Clear

By Burndy
Catalog # [HSTPCL06256IPK25](#)

.625" ID Min (Issued), .313" ID Max (Recovered), Thin Wall, Clear, 6-Inch
Lengths, 25 per package


Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

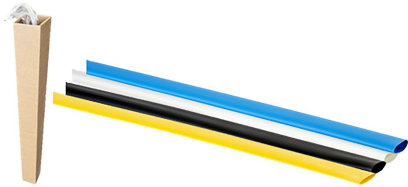

Height	0.03 in
Width	0.625 in
Length	6 in
Dimensions	6 in x 0.625 in x 0.03 in

General

Product Type	Polyolefin Thin Wall Heat Shrink
Color	Clear
UPC	621945695245

Logistics

Carton Quantity	16
-----------------	----

Product Assets

[Catalog \[English\]](#)