




HSTPCL07506IPK25, Heat Shrink Tubing, Thin Wall, Clear

By Burndy
Catalog # [HSTPCL07506IPK25](#)

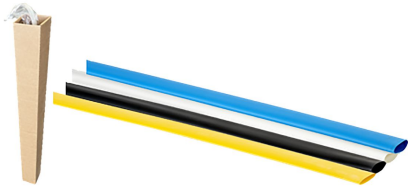

.75" ID Min (Issued), .375" ID Max (Recovered), Thin Wall, Clear, 6-Inch
Lengths, 25 Pieces per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating600 V

Dimensions

Height0.03 in

Width0.75 in
Length6 in
Dimensions6 in x 0.75 in x 0.03 in

General

Product TypePolyolefin Thin Wall Heat Shrink
ColorClear
UPC621945695719

Logistics

Pallet Quantity1
Carton Quantity8

Product Assets

[Catalog \[English\]](#)