



HSTPMX00476IPK25, Heat Shrink Tubing, Thin Wall, Mixed

By Burndy
Catalog # [HSTPMX00476IPK25](#)

.047" ID Min (Issued), .023" ID Max (Recovered), Thin Wall, Mixed
Colors, 6-Inch Lengths, 25 Pieces Total per package


Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

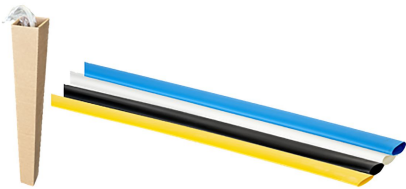

Height	0.016 in
Width	0.047 in
Length	6 in
Dimensions	6 in x 0.047 in x 0.016 in

General

Product Type	Polyolefin Thin Wall Heat Shrink
Color	Multiple Colors
UPC	621945689114

Logistics

Carton Quantity	80
-----------------	----

Product Assets

[Catalog \[English\]](#)