




HSTPMX00636IPK25, Heat Shrink Tubing, Thin Wall, Mixed

By Burndy
Catalog # [HSTPMX00636IPK25](#)

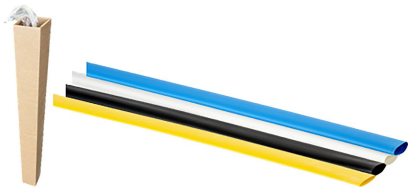

.063" ID Min (Issued), .031" ID Max (Recovered), Thin Wall, Mixed
Colors, 6-Inch Lengths, 25 Pieces Total per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

Height 0.017 in
Width 0.063 in
Package Height 0.000 in

Length 6 in
Package Weight 0.000 lb.
Package Length 0.000 in
Package Width 0.000 in
Dimensions 6 in x 0.063 in x 0.017 in

General

Product Type Polyolefin Thin Wall Heat Shrink
Color Multiple Colors
UPC 621945690561

Logistics

Pallet Quantity 1920
Carton Quantity 80

Product Assets

[Catalog \[English\]](#)