



HSTPMX00946IPK25, Heat Shrink Tubing, Thin Wall, Mixed

By Burndy
Catalog # [HSTPMX00946IPK25](#)


.094" ID Min (Issued), .047" ID Max (Recovered), Thin Wall, Mixed Colors, 6-Inch Lengths, 25 Pieces Total per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Dimensions

Height	0.02 in
Width	0.094 in

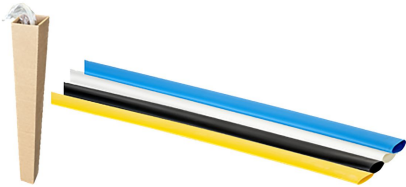

Length	6 in
Dimensions	6 in x 0.094 in x 0.02 in

General

Color	Multiple Colors
UPC	621945691216

Logistics

Pallet Quantity	360
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)