




HSTPMX01256IPK25, Heat Shrink Tubing, Thin Wall, Mixed

By Burndy
Catalog # [HSTPMX01256IPK25](#)

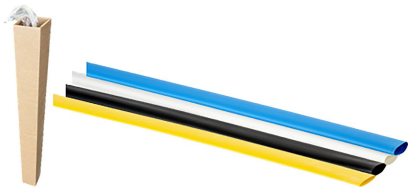

.125" ID Min (Issued), .063" ID Max (Recovered), Thin Wall, Mixed
Colors, 6-Inch Lengths, 25 Pieces Total per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Dimensions

Height	0.02 in
Width	0.0125 in
Package Height	0.000 in
Length	6 in

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimensions	6 in x 0.0125 in x 0.02 in

General

Color	Multiple Colors
UPC	621945691865

Logistics

Pallet Quantity	1920
Carton Quantity	80

Product Assets

[Catalog \[English\]](#)