




HSTPMX01876IPK25, Heat Shrink Tubing, Thin Wall, Mixed

By Burndy
Catalog # [HSTPMX01876IPK25](#)

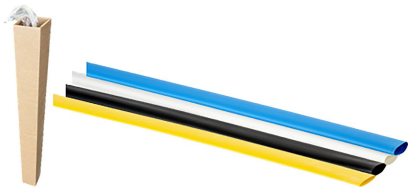

.187" ID Min (Issued), .093" ID Max (Recovered), Thin Wall, Mixed Colors, 6-Inch Lengths, 25 Pieces Total per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Width	0.187 in

Height	0.02 in
Package Height	0.000 in
Length	6 in
Dimensions	6 in x 0.187 in x 0.02 in

General

UPC	621945692589
Color	Multiple Colors

Logistics

Carton Quantity	80
Pallet Quantity	1920

Product Assets

[Catalog \[English\]](#)