



# HSTPOR00476IPK25, Heat Shrink Tubing, Thin Wall, Orange

By Burndy  
Catalog # [HSTPOR00476IPK25](#)

25 Pack 6" Orange Heat Shrink Tubing 3/64" I.D., Thin Wall Polyolefin  
Heat Shrink 600 V

## Features


- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

## Current

Voltage Rating 600 V

## Dimensions

Height 0.016 in

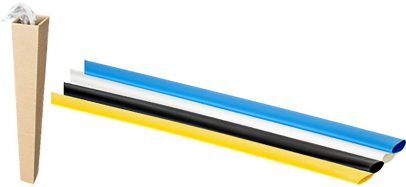

Width 0.047 in  
Length 6 in  
Dimensions 6 in x 0.047 in x 0.016 in

## General

Product Type Polyolefin Thin Wall Heat Shrink  
Color Orange  
UPC 621945690189  
Material Polyolefin

## Logistics

Carton Quantity 80

## Product Assets

[Catalog \[English\]](#)