



HSTPRD10006IPK25, Heat Shrink Tubing, Thin Wall, Red

By Burndy
Catalog # [HSTPRD10006IPK25](#)

1" ID Min (Issued), .5" ID Max (Recovered), Thin Wall, Red, 6-Inch Lengths, 25 Pieces per package

Features


- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

Height 0.035 in

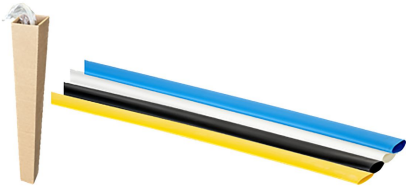

Width 1 in
Length 6 in
Dimensions 6 in x 1 in x 0.035 in

General

Product Type Polyolefin Thin Wall Heat Shrink
Color Red
UPC 621945696327

Logistics

Pallet Quantity 1
Carton Quantity 8

Product Assets

[Catalog \[English\]](#)