



HSTPWH02506IPK25, Heat Shrink Tubing, Thin Wall, White

By Burndy
Catalog # [HSTPWH02506IPK25](#)

.25" ID Min (Issued), .0125" ID Max (Recovered), Thin Wall, White, 6-Inch Lengths, 25 Pieces per package


Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

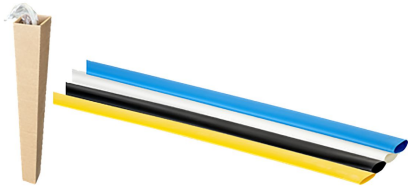

Height	0.025 in
Width	0.25 in
Length	6 in
Dimensions	6 in x 0.25 in x 0.025 in

General

Product Type	Polyolefin Thin Wall Heat Shrink
Color	White
UPC	621945693722

Logistics

Carton Quantity	40
-----------------	----

Product Assets

[Catalog \[English\]](#)