



HSTPYG01256IPK25, Heat Shrink, Thin Wall, Yellow/Green

By Burndy
Catalog # [HSTPYG01256IPK25](#)

.125" ID Min (Issued), .063" ID Max (Recovered), Thin Wall,
Yellow/Green, 6-Inch Lengths, 25 Pieces per package


Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 3:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

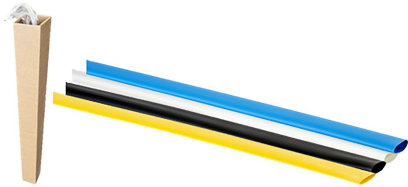

Height	0.02 in
Width	0.0125 in
Length	6 in
Dimensions	6 in x 0.0125 in x 0.02 in

General

Product Type	Polyolefin Thin Wall Heat Shrink
Color	Yellow/Green
UPC	621945692510

Logistics

Carton Quantity	80
-----------------	----

Product Assets

[Catalog \[English\]](#)