



# HSTPYG02506IPK25, Heat Shrink, Thin Wall, Yellow/Green

By Burndy  
Catalog # [HSTPYG02506IPK25](#)

.25" ID Min (Issued), .125" ID Max (Recovered), Thin Wall, Yellow/Green, 6-Inch Lengths, 25 Pieces per package


## Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 3:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

## Current

Voltage Rating 600 V

## Dimensions

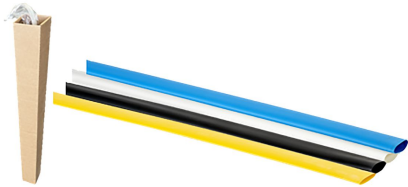

|            |                           |
|------------|---------------------------|
| Height     | 0.025 in                  |
| Width      | 0.25 in                   |
| Length     | 6 in                      |
| Dimensions | 6 in x 0.25 in x 0.025 in |

## General

|              |                                  |
|--------------|----------------------------------|
| Product Type | Polyolefin Thin Wall Heat Shrink |
| Color        | Yellow/Green                     |
| UPC          | 621945693869                     |

## Logistics

|                 |    |
|-----------------|----|
| Carton Quantity | 40 |
|-----------------|----|

## Product Assets

[Catalog \[English\]](#)