



HSTPYL01256IPK25, Heat Shrink Tubing, Thin Wall, Yellow

By Burndy
Catalog # [HSTPYL01256IPK25](#)

.125" ID Min (Issued), .063" ID Max (Recovered), Thin Wall, Yellow, 6-Inch Lengths, 25 Pieces per package


Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

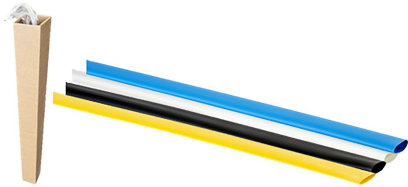

Height	0.02 in
Width	0.0125 in
Length	6 in
Dimensions	6 in x 0.0125 in x 0.02 in

General

Product Type	Polyolefin Thin Wall Heat Shrink
Color	Yellow
UPC	621945692435

Logistics

Carton Quantity	80
-----------------	----

Product Assets

[Catalog \[English\]](#)