




HSTPYL07506IPK25, Heat Shrink Tubing, Thin Wall, Yellow

By Burndy
Catalog # [HSTPYL07506IPK25](#)

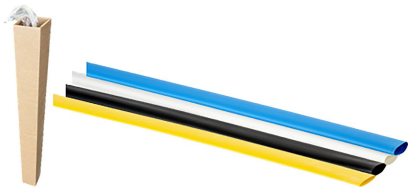

.75" ID Min (Issued), .375" ID Max (Recovered), Thin Wall, Yellow, 6-Inch
Lengths, 25 Pieces per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

Height	0.03 in
Width	0.75 in
Length	6 in
Dimensions	6 in x 0.75 in x 0.03 in

General

Product Type	Polyolefin Thin Wall Heat Shrink
Color	Yellow
UPC	621945695962

Logistics

Carton Quantity	8
-----------------	---

Product Assets

[Catalog \[English\]](#)