




HSTPYL10006IPK25, Heat Shrink Tubing, Thin Wall, Yellow

By Burndy

Catalog # **HSTPYL10006IPK25**

1" ID Min (Issued), .50" ID Max (Recovered), Thin Wall, Yellow, 6-Inch Lengths, 25 Pieces per package

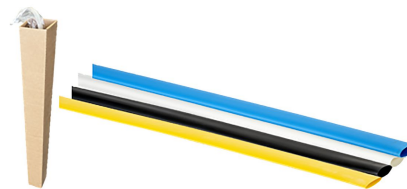

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating	600 V
----------------	-------

Dimensions

Height	0.035 in
Width	1 in
Length	6 in
Dimensions	6 in x 1 in x 0.035 in

General

Product Type	Polyolefin Thin Wall Heat Shrink
Color	Yellow
UPC	621945696426

Logistics

Carton Quantity 8

Product Assets

[Catalog \[English\]](#)

A Hubbell brand