



HT2C58, HammerTap Ground Rod Connection, #4 Str-#2 Str to 5/8" Ground Rod

By Burndy
Catalog # [HT2C58](#)

HT2C58, HYGROUND HammerTap Ground Rod Connection, #4 Str-#2 Str to 5/8" Ground Rod, UL 467 Listed for wire to ground rod

Features

- Irreversible connection option without having to weld
- Does not require special tools for installation
- Minimal training required
- Provides a visual verification that the connection is safely installed correctly
- Fast, easy, and safe connection capable of installation in any environment using just a hammer
- Versatile ground rod clamp, may be used as a termination or a "T" (pass-through) connection

Application


Termination or "T" (pass-through) Ground Rod Connection

Specifications

Industry Standard(s)	• UL 467 • Direct Burial • CSA
----------------------	--

Conductor

Conductor Type	• Cu C Sol-Size • CU Str-Size
----------------	---

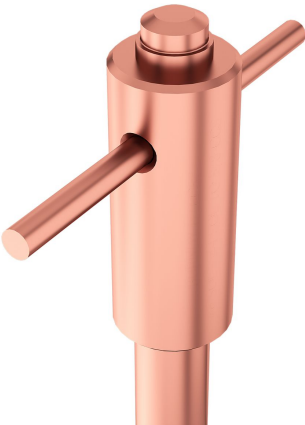

Configuration

Connector Type	Grounding
----------------	-----------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

UPC	621945682108
Material	Copper

Logistics

Pallet Quantity	4500
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)