



HT6C58, HammerTap Ground Rod Connection, #6 Sol-#4 Sol to 5/8" Ground Rod

By Burndy
Catalog # HT6C58

HT6C58, HYGROUND HammerTap Ground Rod Connection, #6 Sol-#4 Sol to 5/8" Ground Rod, UL 467 Listed for wire to ground rod

Features

- Irreversible connection option without having to weld
- Does not require special tools for installation
- Minimal training required
- Provides a visual verification that the connection is safely installed correctly
- Fast, easy, and safe connection capable of installation in any environment using just a hammer
- Versatile ground rod clamp, may be used as a termination or a "T" (pass-through) connection


Application

Termination or "T" (pass-through) Ground Rod Connection

Specifications

Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)
Industry Standard(s)	• UL 467 • Direct Burial • CSA

Conductor

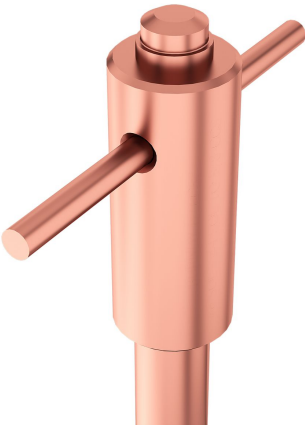

Conductor Type	• Cu C Sol-Size • CU Str-Size
----------------	---

Configuration

Connector Type	Grounding
----------------	-----------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

UPC	621945682092
Material	Copper

Logistics

Carton Quantity	25
-----------------	----

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)