


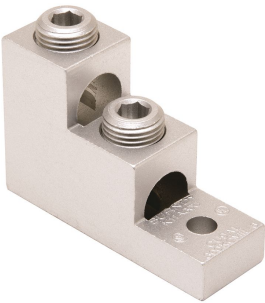

K11A30UG2, AL Universal Terminal, 2-Conductor, 1-Hole

By Burndy
Catalog # [K11A30UG2](#)

2 Conductors: 6 AWG-300 kcmil, 1 Hole, 3/8" Stud, 2 Screws,
AL/CU, Tin Plated



Features

- Dual rated panelboard lugs
- Constructed from high strength, extruded aluminum alloy
- Electro tin-plated to provide low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	6 AWG-300 KCMIL
Number Of Conductors	2
Conductor - AL Str Size Range	6 Str.- 300 Kcmil
Conductor - Copper Str Size Range	6 Str.- 300 Kcmil

Configuration

Physical Attribute - Number of Holes	1
Connector Type	Stacked

Current

Rating - Minimum Voltage	600
--------------------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Dimension - Bolt Size fraction	3/8

Length	3.03 in
Package Weight	0.000 lb.
Dimension - Width inch	1.02 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	77 mm
Height	2.03 in
Width	1.02 in
Dimension - Length Overall inch	3.03 in
Dimension - Stud Size inch	3/8 in
Dimensions	3.03 in x 1.02 in x 2.03 in

General

Plated	N
UPC	781810535752
Type	Bolted Lugs & Terminals
Material	Aluminum
Plating Type	Tin plated
UPC 12 Digit	781810535752
UPC 14 Digit GTIN	00781810535752

Logistics

Minimum Pack Quantity	500
Pallet Quantity	10000
Carton Quantity	500

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)