



K11A36U2N, AL Universal Terminal, 2-Conductor, 2-Hole

By Burndy
Catalog # [K11A36U2N](#)

2-Hole, 2-Conductor #2 AWG-600 kcmil, 1/2" diameter stud holes spaced 1-3/4" on center (NEMA-spacing), 600 Volt Rated, Aluminum, Tin plated

Features

- AL9CU Dual Rated for both copper an aluminum conductor
- Listed to UL Wire Connector Standard UL486A-486B
- 1/2" diameter stud holes spaced 1-3/4" on center (NEMA-spacing)
- Range Taking conductor port

Application

Terminate multiple conductors onto equipment pads, panel boards, or switchgear

Specifications

Buy American Compliant	Contact Manufacturer
EU RoHS Indicator	Contact Manufacturer
Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	Yes


Conductor

Conductor Size	2 AWG-600 KCMIL
----------------	-----------------

Configuration

Connector Type	Stacked
----------------	---------

Dimensions

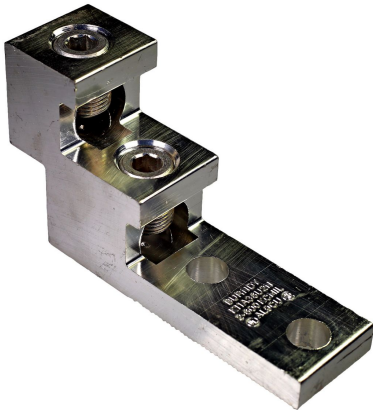

Package Height	2.100 in
Dimension - Bolt Size fraction	1/2
Length	5.34 in
Package Weight	0.850 lb.
Package Length	6.000 in
Package Width	6.500 in
Height	3 in
Width	1.5 in
Dimensions	5.34 in x 1.5 in x 3 in

General

Sub Brand	Terminal
UPC	781810670149
Type	K-A-U2N
Insulation	N
Construction Material - Main	Aluminum
Material	Aluminum
Finish Type	Tin-Plated

Logistics

Minimum Pack Quantity	1
Pallet Quantity	720
Carton Quantity	18

Product Assets

[Catalog \[English\]](#)