




K13P4CAG1, AL Neutral Bar, 13 Circuits, 15 Holes

By Burndy
Catalog # [K13P4CAG1](#)

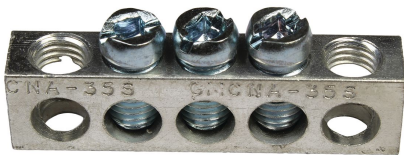

Aluminum neutral bar, 6061-T6 aluminum alloy, tin plated, 14-4 AWG, 13 Circuits

Features

- Steel Zinc Plated Bolt
- CSA Approved
- 600V Minimum Voltage Rating

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	Yes

Configuration

Connector Type	Aluminum Neutral Bar Assembly
----------------	-------------------------------

Current

Rating - Minimum Voltage	600
--------------------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	11.2 mm
Length	4.77 in
Dimension - Height inch	0.44 in
Package Weight	0.000 lb.
Dimension - Width mm	8 mm

Dimension - Width inch	0.31 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	121 mm
Height	0.31 in
Width	0.44 in
Dimension - Length Overall inch	4.77 in
Dimensions	4.77 in x 0.44 in x 0.31 in

General

Plated	N
Material - Bolt	Steel Zinc Plated
UPC	781810665558
Insulation	Y
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810665558
UPC 14 Digit GTIN	00781810665558

Logistics

Minimum Pack Quantity	1
Pallet Quantity	675
Carton Quantity	150

Product Assets

[Catalog \[English\]](#)