


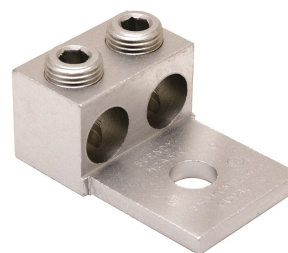

K2A36UG1, AL Universal Terminal, 2-Conductor, 2-Hole

By Burndy
Catalog # [K2A36UG1](#)

2 Conductor, #2 AWG-600 kcmil, 1-Hole, 3/8" Stud, Tin Plated, Dual Rated



Features

- Dual rated panelboard lugs
- Constructed from high strength, extruded aluminum alloy
- Electro tin-plated to provide low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Number Of Conductors	2
Conductor - AL Str Size Range	2 Str. - 600 Kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	2 Str. - 600 Kcmil

Configuration

Physical Attribute - Number of Holes	1
Connector Type	Terminal

Current

Rating - Minimum Voltage	600
--------------------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Length	3.2 in
Package Weight	0.000 lb.
Dimension - Width inch	2.42 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	81 mm
Height	1.58 in
Width	2.42 in
Dimension - Length Overall inch	3.2 in
Dimension - Stud Size inch	3/8 in
Dimensions	3.2 in x 2.42 in x 1.58 in

General

Plated	Y
UPC	781810648414
Type	Bolted Lugs & Terminals
Material	Aluminum
Plating Type	Tin plated
UPC 12 Digit	781810648414
UPC 14 Digit GTIN	00781810648414

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	72

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)