




K2C25TN, SERVIT POST Mechanical Connector, 2 Cables to Flat

By Burndy
Catalog # [K2C25TN](#)

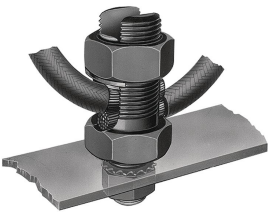

SERVIT POST™ Mechanical Connector, 2 Cables to Flat

Features

- SERVIT POST mechanical connector used to ground 1 or 2 cables to steel structures, fence posts, and transformers
- Also used to tap 1 or 2 cables from bus bar
- 1-Wrench installation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	2 AWG 1 AWG 1/0 AWG
Conductor - Copper Solid Size Range	2 AWG-1/0 AWG
Physical Attribute - Number of Conductors Accommodated Total	2
Conductor - Copper Str Size Range	2 AWG-1/0
Conductor - Copper Str Size	2 AWG 1 AWG 1/0

Dimensions

Dimension - Height mm	39.6 mm
Dimension - Height inch	1.56 in
Dimension - Body Width inch	0.75 in
Dimension - P inch	0.39 in
Dimension - L Length Overall mm	59 mm
Dimension - B Length inch	0.53 in
Dimension - Nut Width inch	0.93 in
Dimension - D inch	0.75 in
Dimension - Length Overall inch	2.31 in

Force Related

Stud Installation Torque inch pounds	180 LBS/in
--------------------------------------	------------

General

Plated	Y
Trade Name	SERVIT POST™
UPC	781810091609
Type	KC and K2C Series
Material	Bronze Alloy, Leaded
Plating Type	Tin Plated
UPC 12 Digit	781810091609
UPC 14 Digit GTIN	00781810091609

Logistics

Minimum Pack Quantity	100
Pallet Quantity	7425
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)