




K2C28B1TN, SERVIT POST Mech Connector, 2 Cables to Flat

By Burndy
Catalog # [K2C28B1TN](#)

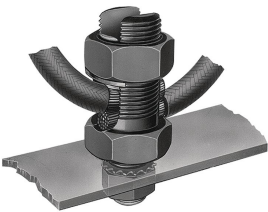

Accepts 2 conductors #1 Str to 4/0 Solid Copper, 5/8" Stud, Tin Plated

Features

- SERVIT POST mechanical connector used to ground 1 or 2 cables to steel structures, fence posts, and transformers
- Also used to tap 1 or 2 cables from bus bar
- 1-Wrench installation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	1 AWG 1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG
Conductor - Copper Solid Size Range	1 AWG-4/0 AWG
Physical Attribute - Number of Conductors Accommodated Total	2
Conductor - Copper Str Size Range	1 AWG-4/0 AWG
Conductor - Copper Str Size	1 AWG 1/0 2/0 AWG 3/0 AWG 4/0 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	62.5 mm
Dimension - Height inch	2.46 in
Dimension - Body Width inch	1.18 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - P inch	0.55 in
Dimension - L Length Overall mm	100 mm
Dimension - B Length inch	1.25 in
Dimension - Nut Width inch	1.35 in
Dimension - D inch	1.50 in
Dimension - Length Overall inch	3.94 in

Force Related

Stud Installation Torque inch pounds	660 LBS/in
--------------------------------------	------------

General

Plated	Y
Trade Name	SERVIT POST™
UPC	621945131279
Type	KC and K2C Series
Material	Copper Alloy
Plating Type	Tin Plated
UPC 12 Digit	621945131279
UPC 14 Digit GTIN	00621945131279

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)