




K2C34B1, SERVIT POST Mechanical Connector, 2 Cables to Flat

By Burndy
Catalog # [K2C34B1](#)

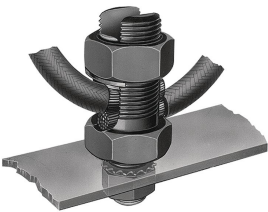

SERVIT POST™ Mechanical Connector, 2 Cables to Flat

Features

- SERVIT POST mechanical connector used to ground 1 or 2 cables to steel structures, fence posts, and transformers
- Also used to tap 1 or 2 cables from bus bar
- 1-Wrench installation

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	• 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil
Physical Attribute - Number of Conductors Accommodated Total	2
Conductor - Copper Str Size Range	3/0 AWG-500 kcmil

Dimensions

Package Height	0.000 in
Dimension - Height mm	60.5 mm

Dimension - Height inch	2.38 in
Dimension - Height fraction	2-3/8
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - P inch	0.85 in
Dimension - L Length Overall mm	104.6 mm
Dimension - Nut Width inch	2.00 in
Dimension - Threads per inch	10
Dimension - Bolt Size fraction	3/4
Dimension - Body Width inch	1.62 in
Dimension - B Length fraction	1-1/2 in
Dimension - B Length inch	1.49 in
Dimension - D inch	1.75 in
Dimension - Length Overall inch	4.12 in

Force Related

Stud Installation Torque inch pounds	1050 LBS/in
--------------------------------------	-------------

General

Trade Name	SERVIT POST™
Plated	N
UPC	781810257753
Type	KC and K2C Series
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810257753
UPC 14 Digit GTIN	00781810257753

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)