



K2P4CAG1, AL Neutral Bar, Dual Rated, 2 Circuits

By Burndy
Catalog # [K2P4CAG1](#)

Aluminum Neutral Bar for Copper/Aluminum Conductor, 14-4 AWG, 2 Circuits

Features

- Dual Rated Aluminum Neutral Bar for Copper and Aluminum
- 2 Circuits, 14-4 AWG wire range
- 600V Minimum Voltage Rating

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	Yes

Conductor


Number Of Conductors	2
Conductor - AL Str Size Range	14-4 AWG
Conductor - Copper Str Size Range	14-4 AWG

Current

Rating - Minimum Voltage	600
--------------------------	-----

Dimensions

Package Height	3.400 in
Dimension - Height mm	11.2 mm
Length	1.09 in

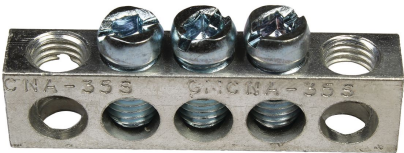

Dimension - Height inch	0.44 in
Package Weight	1.130 lb.
Dimension - Width inch	0.31 in
Package Length	5.500 in
Package Width	4.750 in
Dimension - L Length Overall mm	28 mm
Height	0.31 in
Width	0.44 in
Dimension - Length Overall inch	1.09 in
Dimensions	1.09 in x 0.44 in x 0.31 in

General

Plated	N
UPC	781810665527
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810665527
UPC 14 Digit GTIN	00781810665527

Logistics

Pallet Quantity	40500
Carton Quantity	150

Product Assets

[Catalog \[English\]](#)