




K3P4CAG1, AL Neutral Bar, Dual Rated, 3 Circuits

By Burndy
Catalog # [K3P4CAG1](#)

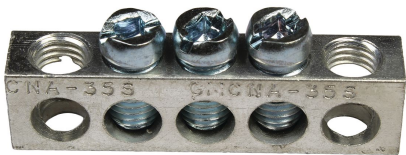

Aluminum Neutral Bar for Copper/Aluminum Conductor, 14-4 AWG, 3 Circuits

Features

- Dual rated lugs
- Constructed from high strength aluminum alloy
- Electro tin plating proving low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	Yes

Conductor

Number Of Conductors	3
Conductor - AL Str Size Range	14-4 AWG
Conductor - Copper Str Size Range	14-4 AWG

Current

Rating - Minimum Voltage	600
--------------------------	-----

Dimensions

Package Height	3.500 in
Dimension - Height mm	11.2 mm
Length	1.67 in

Dimension - Height inch	0.44 in
Package Weight	1.610 lb.
Dimension - Width inch	0.31 in
Package Length	5.400 in
Package Width	4.750 in
Dimension - L Length Overall mm	42 mm
Height	0.44 in
Width	0.31 in
Dimension - Length Overall inch	1.67 in
Dimensions	1.67 in x 0.31 in x 0.44 in

General

Plated	N
UPC	781810665534
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810665534
UPC 14 Digit GTIN	00781810665534

Logistics

Minimum Pack Quantity	1
Pallet Quantity	14400
Carton Quantity	150

Product Assets

[Catalog \[English\]](#)