


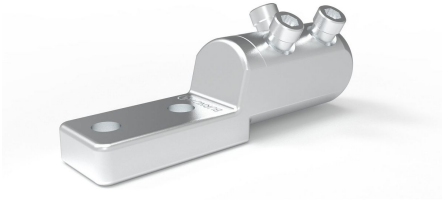

KASB31U2N, QIKSHEAR™ Series, Shear Bolt Lug, 2-hole

By Burndy
Catalog # [KASB31U2N](#)

Mechanical Shear Bolt Lug, Wire Range: 250-350 kcmil, 2-Hole, 1/2" Stud, 1.75" Spacing



Features

- No Tooling or Die Investment Required, no crimp tools necessary
- Dual Rated AL9CU for use with both copper and aluminum conductor
- cULus Listed Wire Connector to UL486A-486B
- Up to 35kV voltage rating
- Tin Plated aluminum connectors and bolts reduce galvanic corrosion and oxide build up
- Range-taking capabilities on most sizes

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Width	1.22 in
Height	1.6 in

Package Height	0.000 in
Length	5.9 in
Dimensions	5.9 in x 1.22 in x 1.6 in

General

Type	Bolted Lugs & Terminals
Series	QIKSHEAR™ Series
UPC	621945658905

Logistics

Carton Quantity	14
Pallet Quantity	3276

Product Assets

- [Catalog \[English\]](#)
[Installation Manual \[English\]](#)