


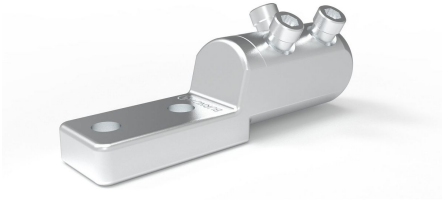

KASB34U2N, QIKSHEAR™ Series, Shear Bolt Lug, 2-hole

By Burndy
Catalog # [KASB34U2N](#)

Mechanical Shear Bolt Lug, Wire Range: 350-500 kcmil, 2-Hole, 1/2" Stud, 1.75" Spacing



Features

- No Tooling or Die Investment Required, no crimp tools necessary
- Dual Rated AL9CU for use with both copper and aluminum conductor
- cULus Listed Wire Connector to UL486A-486B
- Up to 35kV voltage rating
- Tin Plated aluminum connectors and bolts reduce galvanic corrosion and oxide build up
- Range-taking capabilities on most sizes

Dimensions

Package Height	0.000 in
Length	6.95 in
Package Weight	0.000 lb.

Package Length	0.000 in
Package Width	0.000 in
General	
UPC	621945652385
Type	Bolted Lugs & Terminals
Series	QIKSHEAR™ Series

Logistics

Pallet Quantity	1680
Carton Quantity	20

Product Assets

- [Catalog \[English\]](#)
- [Installation Manual \[English\]](#)