



KASB39U2N, QIKSHEAR™ Series, Shear Bolt Lug, 2-hole

By Burndy
Catalog # [KASB39U2N](#)


Mechanical Shear Bolt Lug, Wire Range: 600-750 kcmil, 2-Hole,
1/2" Stud, 1.75" Spacing

Features

- No Tooling or Die Investment Required, no crimp tools necessary
- Dual Rated AL9CU for use with both copper and aluminum conductor
- cULus Listed Wire Connector to UL486A-486B
- Up to 35kV voltage rating
- Tin Plated aluminum connectors and bolts reduce galvanic corrosion and oxide build up
- Range-taking capabilities on most sizes

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Width	1.67 in
Height	2 in

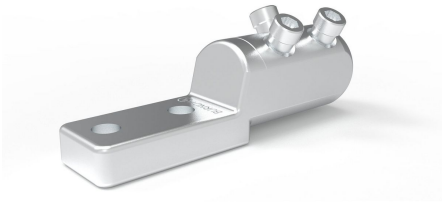

Package Height	0.000 in
Length	6.95 in
Dimensions	6.95 in x 1.67 in x 2 in

General

Type	Bolted Lugs & Terminals
Series	QIKSHEAR™ Series
UPC	621945652392

Logistics

Carton Quantity	20
Pallet Quantity	1680

Product Assets

- [Catalog \[English\]](#)
[Installation Manual \[English\]](#)