


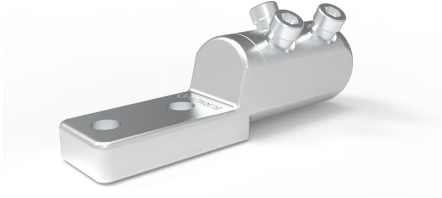

KASB44U2N, QIKSHEAR™ Series, Shear Bolt Lug, 2-hole

By Burndy
Catalog # [KASB44U2N](#)

Mechanical Shear Bolt Lug, Wire Size: 1000 kcmil, 2-Hole, 1/2" Stud, 1.75" Spacing



Features

- No Tooling or Die Investment Required, no crimp tools necessary
- Dual Rated AL9CU for use with both copper and aluminum conductor
- cULus Listed Wire Connector to UL486A-486B
- Up to 35kV voltage rating
- Tin Plated aluminum connectors and bolts reduce galvanic corrosion and oxide build up
- Range-taking capabilities on most sizes

Conductor

Wire Range 1000 kcmil (Class B & C)

Dimensions

Dimension - Pad Width inch 1.75
Package Height 6.625 in
Length 6.95 in

Package Weight 16.940 lb.
Package Length 14.563 in
Outside Diameter 2.01
Package Width 8.313 in
Dimension - Stud Size inch 1/2"

General

UPC 621945637504
Type Bolted Lugs & Terminals
Hex Key 5/16"
Series QIKSHEAR™ Series

Logistics

Pallet Quantity 1092
Carton Quantity 14

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)