



KCKF23, Mechanical Bulkhead Ground Connector Kit

By Burndy
Catalog # [KCKF23](#)

Mechanical Bulkhead Ground Connector Kit; includes SERVIT® Split bolts; SERVIT POST™ Connectors and Installation Hardware

Features

- Designed to allow a ground wire to be connected from the inside of a box or enclosure to the outside of a box or enclosure

Application


Designed to allow a ground wire to be connected from the inside of a box or enclosure to the outside of a box or enclosure

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	UI
Status	
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	BABA Compliant (All status valid till December 2026)
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	10 AWG 9 AWG 8 AWG 7 AWG 6 AWG 5 AWG 4 AWG 3 AWG 2 AWG 1 AWG
Conductor - Copper Solid Size Range	10 AWG-1 AWG
Conductor - Copper Str Size Range	8 AWG-2 AWG
Conductor - Copper Str Size	8 AWG 7 AWG 6 AWG 5 AWG

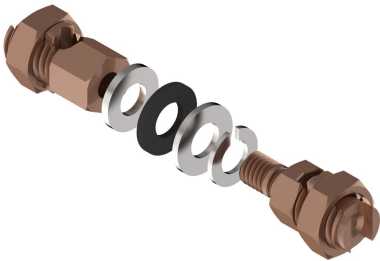

- 4 AWG
- 3 AWG
- 2 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

Force Related

Stud Installation Torque inch pounds	100 LBS/in
--------------------------------------	------------

General

Plated	No
Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Bar/Flat
Trade Name	SERVIT POST™
Sub Brand	SERVIT POST
Product Type	Mechanical
UPC	781810567432
Type	Bulkhead Servit
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810567432
UPC 14 Digit GTIN	00781810567432

Logistics

Minimum Pack Quantity	1
Pallet Quantity	4640
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)