


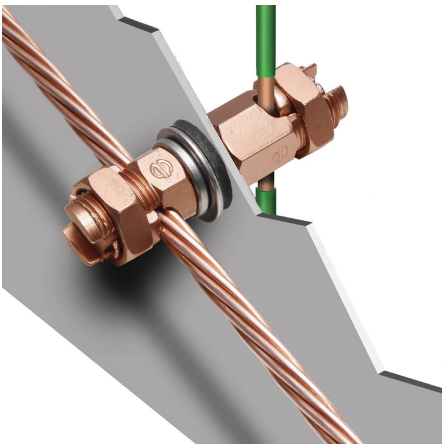

KCKF28, Mechanical Bulkhead Ground Connector Kit

By Burndy
Catalog # [KCKF28](#)

Mechanical Bulkhead Ground Connector Kit; includes SERVIT® Split bolts; SERVIT POST™ Connectors and Installation Hardware



Features

- Designed to allow a ground wire to be connected from the inside of a box or enclosure to the outside of a box or enclosure

Application

Designed to allow a ground wire to be connected from the inside of a box or enclosure to the outside of a box or enclosure

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	1 AWG 1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG
Conductor - Copper Solid Size Range	1 AWG-4/0 AWG
Conductor - Copper Str Size Range	1 AWG-4/0 AWG
Conductor - Copper Str Size	1 AWG 1/0 2/0 AWG 3/0 AWG 4/0 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

Force Related

Stud Installation Torque inch pounds	250 LBS/in
--------------------------------------	------------

General

Plated	No
Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Bar/Flat
Trade Name	SERVIT POST™
Sub Brand	SERVIT POST
Product Type	Mechanical
UPC	781810635773
Type	Bulkhead Servit
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810635773
UPC 14 Digit GTIN	00781810635773

Logistics

Minimum Pack Quantity	1
Pallet Quantity	208
Carton Quantity	13

Product Assets

[Catalog \[English\]](#)