



KK6A31U8, AL Universal Term, 6-Conductor, 8-Hole, Dual Rated

By Burndy
Catalog # [KK6A31U8](#)

Universal Terminals, Accepts up to 6 Conductors, #12 AWG-350 kcmil, 8 Mounting Holes, 1/2" Stud Holes, 1.75" Spacing

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Contact Manufacturer
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No


Conductor

Conductor Size	6 AWG-350 KCMIL
Number Of Conductors	6
Number Of Wires	6
Conductor - AL Str Size Range	12 Str. - 350 Kcmil
Conductor Type	- CU C Str-Size - AL C Str-Size
Conductor - Copper Str Size Range	12 Str. - 350 Kcmil

Configuration

Number of Holes	8
Physical Attribute - Number of Holes	8
Connector Type	Parallel Set-Screw

Dimensions

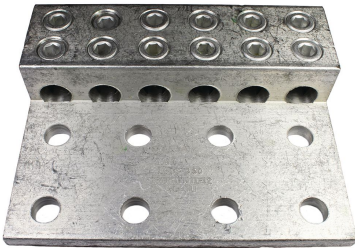

Package Height	4.250 in
Dimension - Height mm	38.1 mm
Dimension - Bolt Size fraction	9/16
Length	6.75 in
Dimension - Height inch	1.5 in
Package Weight	4.820 lb.
Package Length	8.750 in
Package Width	8.300 in
Dimension - L Length Overall mm	171 mm
Height	1.5 in
Width	5.31 in
Dimension - Length Overall inch	6.75 in
Dimension - Stud Size fraction	9/16
Dimensions	6.75 in x 5.31 in x 1.5 in

General

Plated	Y
Sub Brand	Universal Terminals
UPC	781810666630
Type	KK6A-U
Construction Material - Main Material	Aluminum
Plating Type	Clear plated
Finish Type	Clear Plate
UPC 14 Digit GTIN	00781810666630

Logistics

Minimum Pack Quantity	1
Pallet Quantity	288
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)