


KK6A34U8, AL Universal Term, 6-Conductor, 8-Hole, Dual Rated

By Burndy

Catalog # [KK6A34U8](#)

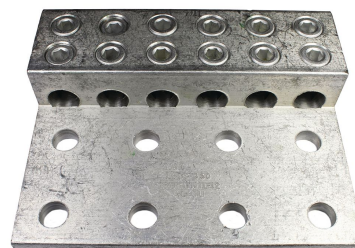

Universal Terminal, 6-Conductors, 8 Mounting Holes, 1/2" Stud, 1.75" Spacing, #2 AWG-500 kcmil, Dual Rated

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Contact Manufacturer
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor Size	2 AWG-500 KCMIL
Number Of Conductors	6
Number Of Wires	6
Conductor - AL Str Size Range	10 Str. - 500 Kcmil
Conductor Type	- CU C Str-Size - AL C Str-Size
Conductor - Copper Str Size Range	10 Str. - 500 Kcmil

Configuration

Number of Holes	8
Physical Attribute - Number of Holes	8
Connector Type	Parallel Set-Screw

Dimensions

Package Height	4.250 in
Dimension - Height mm	38.1 mm
Dimension - Bolt Size fraction	9/16
Length	6.75 in
Dimension - Height inch	1.5 in
Package Weight	4.690 lb.
Package Length	8.750 in
Package Width	8.400 in
Dimension - L Length Overall mm	171 mm
Height	2.13 in
Width	5.56 in
Dimension - Length Overall inch	6.75 in
Dimension - Stud Size fraction	9/16
Dimensions	6.75 in x 5.56 in x 2.13 in

General

Plated	Y
Sub Brand	Universal Terminals
UPC	781810666654
Type	KK6A-U
Construction Material - Main Material	Aluminum
Plating Type	Clear plated
Finish Type	Clear Plate Cms-14
UPC 14 Digit GTIN	00781810666654

Logistics

Minimum Pack Quantity	1
Pallet Quantity	288
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)