


KK6A44U12, Universal Term, 6-Conductor, 12-Hole, Dual Rated

By Burndy
 Catalog # [KK6A44U12](#)

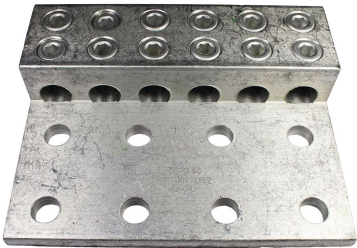

6-Conductor Connector, 350-1000 kcmil AL/CU, 12-Hole pad, 1/2" Stud, 1.75" Spacing, Dual Rated

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Contact Manufacturer
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor Size	350-1000 KCMIL
Number Of Conductors	6
Number Of Wires	6
Conductor - AL Str Size Range	350 Kcmil - 1000 Kcmil
Conductor Type	- CU C Str-Size - AL C Str-Size
Conductor - Copper Str Size Range	350 Kcmil - 1000 Kcmil

Configuration

Number of Holes	12
Physical Attribute - Number of Holes	12
Connector Type	Parallel Set-Screw

Dimensions

Dimension - Pad Width inch	3.44 in
----------------------------	---------

Package Height	4.250 in
Dimension - Height mm	47.8 mm
Dimension - Bolt Size fraction	9/16
Length	10.5 in
Dimension - Height inch	1.88 in
Package Weight	11.760 lb.
Package Length	12.600 in
Package Width	6.500 in
Dimension - L Length Overall mm	267 mm
Height	1.88 in
Width	6.19 in
Dimension - Length Overall inch	10.50 in
Dimension - Stud Size fraction	9/16
Dimensions	10.5 in x 6.19 in x 1.88 in

General

Plated	Y
Sub Brand	Universal Terminals
UPC	781810666692
Type	KK6A-U
Construction Material - Main Material	Aluminum
Plating Type	Clear plated
Finish Type	Clear Plate Cms-14
UPC 14 Digit GTIN	00781810666692

Logistics

Minimum Pack Quantity	1
Pallet Quantity	192
Carton Quantity	6

Product Assets

[Catalog \[English\]](#)