




KK8A31U10, Univ. Term, 8-Cond., 10-Hole, PENETROX

By Burndy

Catalog # [KK8A31U10](#)

8-Conductor #6-350 kcmil AL/CU, 10-Hole Pad, 1/2" Stud, 1.75" Spacing, Dual Rated, Oxide inhibitor pre-applied

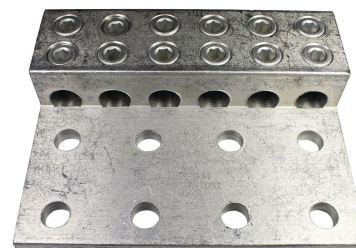

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor Size	6 AWG-350 KCMIL
Number Of Conductors	8
Number Of Wires	8
Conductor - AL Str Size Range	12 Str. - 350 Kcmil
Conductor Type	- CU C Str-Size - AL C Str-Size
Conductor - Copper Str Size Range	12 Str. - 350 Kcmil

Configuration

Physical Attribute - Number of Holes	10
Connector Type	Parallel Set-Screw

Dimensions

Dimension - Pad Width inch	3.43 in
Package Height	3.800 in

Dimension - Height mm	38.1 mm
Dimension - Bolt Size fraction	9/16
Length	8.75 in
Dimension - Height inch	1.5 in
Package Weight	6.100 lb.
Package Length	10.250 in
Package Width	5.600 in
Dimension - L Length Overall mm	222 mm
Height	1.5 in
Width	5.31 in
Dimension - Length Overall inch	8.75 in
Dimension - Stud Size fraction	9/16
Dimensions	8.75 in x 5.31 in x 1.5 in

General

Plated	Y
UPC	781810666647
Type	Bolted Lugs & Terminals
Material	Aluminum
Plating Type	Clear plated
Finish Type	Clear Plate
UPC 14 Digit GTIN	00781810666647

Logistics

Minimum Pack Quantity	1
Pallet Quantity	384
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)