


# KK8A34U10, Univ. Term, 8-Cond., 10-Hole, PENETROX

By Burndy  
Catalog # [KK8A34U10](#)

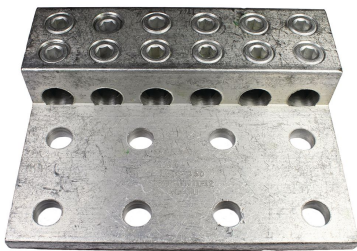

8-Conductor #2-500 kcmil AL/CU, 10-Hole Pad, 1/2" Stud, 1.75" Spacing, Dual Rated, Oxide inhibitor pre-applied

### Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

### Specifications

|                               |                      |
|-------------------------------|----------------------|
| Certification - ETL           | No                   |
| Certification - UL Recognized | No                   |
| Standards - RoHS Compliance   | CM                   |
| Status                        |                      |
| Buy American Compliant        | Contact Manufacturer |
| Certification - cULus         | No                   |
| EU RoHS Indicator             | Contact Manufacturer |
| Buy America(n) Qualified      | Contact Manufacturer |
| UL Listed                     | No                   |
| Certification - CSA Approved  | No                   |

### Conductor

|                                   |                                                                                     |
|-----------------------------------|-------------------------------------------------------------------------------------|
| Conductor Size                    | 2 AWG-500 KCMIL                                                                     |
| Number Of Conductors              | 8                                                                                   |
| Number Of Wires                   | 8                                                                                   |
| Conductor - AL Str Size Range     | 10 Str. - 500 Kcmil                                                                 |
| Conductor Type                    | <ul style="list-style-type: none"><li>CU C Str-Size</li><li>AL C Str-Size</li></ul> |
| Conductor - Copper Str Size Range | 10 Str. - 500 Kcmil                                                                 |

### Configuration

|                                      |                    |
|--------------------------------------|--------------------|
| Number of Holes                      | 10                 |
| Physical Attribute - Number of Holes | 10                 |
| Connector Type                       | Parallel Set-Screw |

### Dimensions

|                            |         |
|----------------------------|---------|
| Dimension - Pad Width inch | 3.43 in |
|----------------------------|---------|

|                                 |                            |
|---------------------------------|----------------------------|
| Package Height                  | 4.250 in                   |
| Dimension - Height mm           | 38.1 mm                    |
| Dimension - Bolt Size fraction  | 9/16                       |
| Length                          | 8.75 in                    |
| Dimension - Height inch         | 1.5 in                     |
| Package Weight                  | 5.990 lb.                  |
| Package Length                  | 12.500 in                  |
| Package Width                   | 6.500 in                   |
| Dimension - L Length Overall mm | 222 mm                     |
| Height                          | 1.5 in                     |
| Width                           | 5.56 in                    |
| Dimension - Length Overall inch | 8.75 in                    |
| Dimension - Stud Size fraction  | 9/16                       |
| Dimensions                      | 8.75 in x 5.56 in x 1.5 in |

### General

|                                       |                     |
|---------------------------------------|---------------------|
| Plated                                | Y                   |
| Sub Brand                             | Universal Terminals |
| UPC                                   | 781810666661        |
| Type                                  | KK8A-U              |
| Construction Material - Main Material | Aluminum            |
| Plating Type                          | Clear plated        |
| Finish Type                           | Clear Plate Cms-14  |
| UPC 14 Digit GTIN                     | 00781810666661      |

### Logistics

|                       |     |
|-----------------------|-----|
| Minimum Pack Quantity | 1   |
| Pallet Quantity       | 180 |
| Carton Quantity       | 12  |

### Product Assets

[Catalog \[English\]](#)