



KK8A39U12, Univ. Term, 8-Cond., 12-Hole, PENETROX

By Burndy
Catalog # [KK8A39U12](#)

8 Conductor, #2-750 kcmil AL/CU, 12-Hole Pad, 1/2" Stud, 1.75" Spacing, Dual Rated, Oxide inhibitor pre-applied

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

Conductor


Conductor Size	2 AWG-750 KCMIL
Number Of Conductors	8
Number Of Wires	8
Conductor - AL Str Size Range	2 Str. - 750 Kcmil
Conductor Type	- CU C Str-Size - AL C Str-Size
Conductor - Copper Str Size Range	2 Str. - 750 Kcmil

Configuration

Number of Holes	12
Physical Attribute - Number of Holes	12
Connector Type	Parallel Set-Screw

Dimensions

Dimension - Pad Width inch	3.44 in
----------------------------	---------

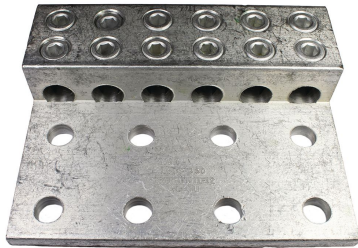

Package Height	4.250 in
Dimension - Height mm	47.8 mm
Dimension - Bolt Size fraction	9/16
Length	10.5 in
Dimension - Height inch	1.63 in
Package Weight	8.920 lb.
Package Length	12.500 in
Package Width	6.600 in
Dimension - L Length Overall mm	267 mm
Height	1.63 in
Width	5.94 in
Dimension - Length Overall inch	10.50 in
Dimension - Stud Size fraction	9/16
Dimensions	10.5 in x 5.94 in x 1.63 in

General

Plated	Y
Sub Brand	Universal Terminals
UPC	781810666685
Type	KK8A-U
Construction Material - Main Material	Aluminum
Plating Type	Clear plated
Finish Type	Clear Plate Cms-14
UPC 14 Digit GTIN	00781810666685

Logistics

Minimum Pack Quantity	1
Pallet Quantity	288
Carton Quantity	8

Product Assets

[Catalog \[English\]](#)