



KK8A44U14, Univ Term, 8-Conductor, 14-Hole, PENETROX

By Burndy
Catalog # [KK8A44U14](#)

Universal Terminal, 8 Conductors, 350-1000 kcmil, 14 Mounting Holes, 9/16" Stud Holes, Dual Rated

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor


Conductor Size	350-1000 KCMIL
Number Of Conductors	8

Configuration

Connector Type	Parallel Set-Screw
----------------	--------------------

Dimensions

Dimension - Pad Width inch	12.12 in
Package Height	0.000 in
Dimension - Height mm	47.8 mm
Dimension - Bolt Size fraction	9/16
Length	12.25 in
Dimension - Height inch	1.88 in

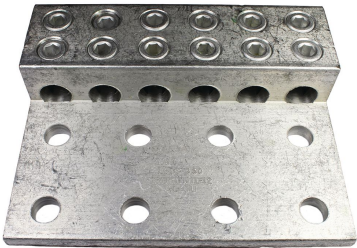

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Height	1.88 in
Width	6.19 in
Dimension - D inch	6.19 in
Dimension - Stud Size fraction	9/16
Dimensions	12.25 in x 6.19 in x 1.88 in

Force Related

Installation Torque	550
Recommended in-lb	

General

Plated	Y
UPC	781810666708
Type	Bolted Lugs & Terminals
Material	Aluminum
Plating Type	Clear plated
Finish Type	Clear Plate Cms-14
UPC 14 Digit GTIN	00781810666708

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	6

Product Assets

[Catalog \[English\]](#)