


KLU300TP, Cu Mechanical, Offset Tongue, Range Taking, 1-Hole

By Burndy
Catalog # [KLU300TP](#)

Offset Tongue Terminal for Cu, 1/0 Str-350 kcmil, 3/8" Stud, Tin Plated

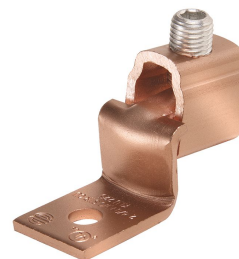

Features

- Range-taking design reduces SKUs required in inventory
- High conductivity copper alloy for long lasting reliable contact
- Compact design, easy to install
- Slot Robertson screw, hex head, hex socket bolt require no special installation tools

Specifications

Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - cULus	Yes
Certification - UL Listed Direct Burial	No
Industry Standard(s)	UL467
Certification - CSA Approved	Yes

Conductor

Conductor Size	1/0 AWG-350 KCMIL
Conductor Type	CU C Str-Size
Conductor - Copper Str Size Range	1/0 -350 kcmil
Conductor - Copper Str Size	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil

Configuration

Physical Attribute - Number of Screws	1
Physical Attribute - Number of Holes	1
Connector Type	Pressure Bar

Dimensions

Dimension - Pad Width inch	0.99 in
Package Height	0.000 in
Dimension - Height mm	0 mm
Dimension - Bolt Size fraction	3/8
Dimension - B Length fraction	1-7/32 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	72 mm
Dimension - B Length inch	1.22 in
Dimension - N inch	0.52 in
Dimension - Hole Size mm	10 mm
Dimension - Hole Size inch	0.39 in
Dimension - Screw Size inch	5/8
Dimension - Length Overall inch	2.83 in
Dimension - Strip Length inch	1-5/8
Dimension - Stud Size inch	3/8

Force Related

Installation Torque	275
Recommended in-lb	

General

Physical Attribute - Screw Type	Allen
Plated	Y
Trade Name	SCRULUG™
UPC	621945467736
Type	Bolted Lugs & Terminals
Material	Copper
Plating Type	Tin
Hardware Type	5/8 UNF Socket/HexScrew
UPC 14 Digit GTIN	00781810352809

Logistics

Minimum Pack Quantity	10
Pallet Quantity	11600
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)