


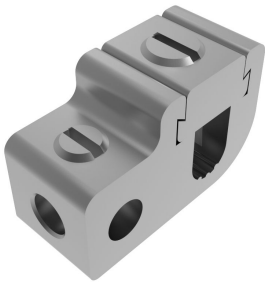

KPU2C4CT, Connector Only, Insulated Gutter Tap

By Burndy
Catalog # [KPU2C4CT](#)

Connector Only, #12 AWG-2 AWG Run, #14-4 AWG Cu, #1 AWG-4 AWG Al, Yellow Cover available



Features

- 600 Volt Rated
- AL9CU dual rated for use with aluminum or copper conductor
- UL Listed to UL486A-B, CSA Certified to C22.2 No. 65
- Manufactured from high strength 6061-T6 aluminum alloy
- Electro tin plated for low contact resistance and protection against corrosion
- Tap parallel or perpendicular to run conductor
- Connectors are re-useable

Conductor

Conductor - AL Str Run Range	12 AWG - 2 AWG
Conductor - AL Str Tap Range	12 AWG - 4 AWG
Conductor - Copper Str Run Range	12 AWG - 2 AWG

Conductor - Copper Str Tap Range	14 AWG - 4 AWG
----------------------------------	----------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

UPC	621945657526
-----	--------------

Product Assets

[Catalog \[English\]](#)