


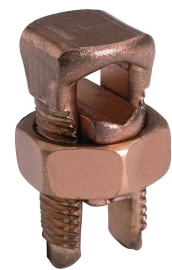

KS15, Split Bolt Connector, Run/Tap: #10-8 AWG Str

By Burndy
Catalog # [KS15](#)

Copper Split Bolt, Cu: 10-8 AWG (Str) (Run & Tap)



Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Applications In Earth Or Concrete, Copper

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	• UL486 • UL467 • CSA C22.2 No 41
Certification - ETL	No
Standards - Industry Standards Met	• UL486 • UL467 • CSA C22.2 No 41
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	10 STR - 8 STR
Conductor - Copper Str Run	• 10 AWG • 9 AWG • 8 AWG
Conductor - Copper Solid Run Range	10 AWG-8 AWG
Conductor - Copper Solid Run	8 AWG
Conductor - Copper Solid Tap Range	14 AWG-8 AWG
Conductor - Copper Solid Tap	8 AWG
Conductor - CopperWeld Solid Tap Range	#8
Conductor - CopperWeld Solid Tap	#8

Conductor - CopperWeld Str Run Range	#8
Conductor - CopperWeld Str Run	#8
Conductor Type	• CU C Solid-Run • CU C Str-Run • CU Weld C Solid-Run • CU Weld C Str-Run • CU C Str-Tap • CU Weld C Solid-Tap • CU Weld C Str-Tap • CU C Solid-Tap
Conductor - Copper Str Tap Range	10 STR - 8 STR
Conductor - Copper Str Tap	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	22 mm
Width	0.38 in
Dimension - Width fraction	19/50 in
Dimension - B Length fraction	9/20 in
Dimension - Width mm	10 mm
Dimension - Width inch	0.38 in
Dimension - B Length inch	.45 in
Dimension - Cross Flats inch	0.50 in
Dimension - Length Overall inch	0.85

Force Related

Installation Torque	80 in-lbs
Recommended in-lb	

General

Trade Name	SERVIT®	UPC 14 Digit GTIN	00781810011256
Plated	N	Logistics	
Sub Brand	SERVIT		
UPC	781810011256		
Type	KS, Compact	Pallet Quantity	99000
Material	Copper	Carton Quantity	100
Plating Type	Unplated	Product Assets	
UPC 12 Digit	781810011256		
		Catalog [English]	



A Hubbell brand