


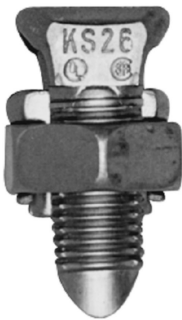

KS15NK, Split Bolt Connector, Run: #10 Str- #8 Sol, Tap: #14-#8 AWG, Nickel Plated

By Burndy
Catalog # [KS15NK](#)

Cu Alloy SERVIT Split Bolt, #10 Str. - #8 Sol.(Run), #14 - #8
AWG(Tap), Nickel Plated



Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Specifications

Standards - Industry Standards Met	UL486D
Standards - RoHS Compliance Status	CM
Industry Standard(s)	UL486D
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	10 STR - 8 STR
Conductor - Copper Solid Run	8 AWG
Conductor - Copper Solid Tap	8 AWG
Conductor Type	• CU C Solid-Run • CU C Str-Run • CU Weld C Str-Run • CU C Solid-Tap • CU C Str-Tap • CU Weld C Str-Tap
Conductor - Copper Str Tap Range	10 STR - 8 STR

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Width	0.38 in
Dimension - Length Overall	0.85 inch

General

Plated	Y
Trade Name	SERVIT®
UPC	781810095584
Material	Copper
Plating Type	Nickel
UPC 12 Digit	781810095584
UPC 14 Digit GTIN	00781810095584

Logistics

Minimum Pack Quantity	1
Pallet Quantity	89100
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)