



KS17NK, Split Bolt Connector, Run: #8 Str- #6 Sol, Tap: #14-#6 Str, Nickel Plated

By Burndy
Catalog # [KS17NK](#)

Cu Alloy SERVIT Split Bolt, #8 Str. - #6 Sol.(Run), #14 - #6 Str.
(Tap), Nickel Plated

Features


- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL486D
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Industry Standard(s)	UL486D
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	8 STR - 6 STR
Conductor - Copper Solid Run	6 AWG
Conductor - Copper Solid Tap	6 AWG
Conductor Type	• CU C Solid-Run • CU C Str-Run • CU Weld C Str-Run • CU C Solid-Tap • CU C Str-Tap

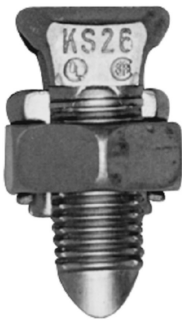

Conductor - Copper Str Tap Range	• CU Weld C Str-Tap 8 STR - 6 STR
----------------------------------	---

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Width	0.45 in
Dimension - Length Overall	1.14 inch

General

Plated	Y
Trade Name	SERVIT®
UPC	781810089323
Material	Copper
Plating Type	Nickel
UPC 12 Digit	781810089323
UPC 14 Digit GTIN	00781810089323

Logistics

Minimum Pack Quantity	1
Pallet Quantity	9900
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)