




**KS203, Split Bolt Connector, Run/Tap: #8
AWG Str-#4 AWG Sol**

By Burndy
Catalog # [KS203](#)

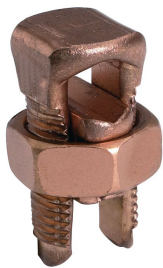

Copper Split Bolt, Cu: 8 AWG (Str)-4 AWG (Sol) (Run & Tap)

Features

- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Copper, Copperweld, Direct Burial Cables

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	BABA Compliant (All status valid till December 2026)
Industry Standard(s)	RUS
Certification - ETL	No
Standards - Industry Standards Met	RUS
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	8 STR - 4 STR
Conductor - Copper Str Run	• 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG
Conductor - Copper Solid Run Range	4 AWG
Conductor - Copper Solid Run	4 AWG
Conductor - Copper Solid Tap	4 AWG
Conductor - CopperWeld Solid Tap Range	10 AWG-4 AWG
Conductor - CopperWeld Solid Tap	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG
Conductor - CopperWeld Solid Run Range	10 AWG-4 AWG
Conductor - CopperWeld Solid Run	• 10 AWG

	• 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG
Conductor - CopperWeld Str Tap Range	8 D AWG-6 A AWG
Conductor - CopperWeld Str Tap	• 8 D AWG • 7 A AWG • 7 D AWG • 6 A AWG
Conductor - CopperWeld Str Run Range	8 D AWG-6 A AWG
Conductor - CopperWeld Str Run	• 8 D AWG • 7 A AWG • 7 D AWG • 6 A AWG
Conductor Type	• CU C Solid-Run • CU C Str-Run • CU Weld C Solid-Run • CU Weld C Str-Run • CU C Str-Tap • CU Weld C Solid-Tap • CU Weld C Str-Tap
Conductor - Copper Str Tap Range	8 STR - 4 STR
Conductor - Copper Str Tap	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	30 mm
Width	0.51 in

Dimension - Width mm20 mm
Dimension - Width inch0.78 in
Dimension - Cross Flats inch.68 in
Dimension - Length Overall inch1.2

Force Related

Installation Torque Recommended165 LBS/in
in-lb

General

Product FamilyPower Connectors>Split Bolts>KS
Trade NameSERVIT®
PlatedNo
Sub BrandSERVIT
Product TypeMechanical

UPC781810022009
TypeKS-3
MaterialCopper
Plating TypeUnplated
UPC 12 Digit781810022009
UPC 14 Digit GTIN00781810022009

Logistics

Minimum Pack Quantity1
Pallet Quantity29700
Carton Quantity100

Product Assets

[Catalog \[English\]](#)

