




KS22, Split Bolt Connector, Run/Tap: #8 AWG Str-6 AWG Sol

By Burndy
Catalog # [KS22](#)

Copper Split Bolt Connectors

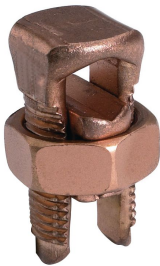

Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Applications In Earth Or Concrete, Copper

Specifications

Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	Contact Manufacturer
EU RoHS Indicator	Yes
Buy America(n) Qualified	BABA Compliant (All status valid till December 2026)
UL Listed	Yes
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

Sub Brand	SERVIT
UPC	781810012505
Type	KS, Compact
Material	Copper

Logistics

Minimum Pack Quantity	1
Pallet Quantity	52800
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)