


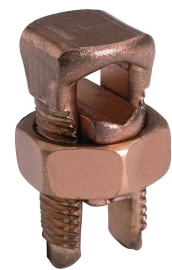

**KS223, Split Bolt Connector, Run/Tap: #6
AWG Str-#2 AWG Sol**

By Burndy
Catalog # [KS223](#)

Copper Split Bolt, Cu: 6 AWG (Str)-2 AWG (Sol) (Run & Tap)



Features

- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Applications, Copper, Copperweld

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Buy America(n) Qualified	BABA Compliant (All status valid till December 2026)
Industry Standard(s)	RUS
Certification - ETL	No
Standards - Industry Standards Met	RUS
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	6 STR - 3 STR
Conductor - Copper Str Run	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - Copper Solid Run Range	2 AWG
Conductor - Copper Solid Run	2 AWG
Conductor - Copper Solid Tap	2 AWG
Conductor - CopperWeld Solid Tap Range	8 AWG-4 AWG
Conductor - CopperWeld Solid Tap	• 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG
Conductor - CopperWeld Solid Run Range	8 AWG-4 AWG
Conductor - CopperWeld Solid Run	• 8 AWG • 7 AWG • 6 AWG

	• 5 AWG • 4 AWG
Conductor - CopperWeld Str Tap Range	6 D AWG-4 A AWG
Conductor - CopperWeld Str Tap	• 6 D AWG • 5 A AWG • 5 D AWG • 5 P AWG • 4 A AWG
Conductor - CopperWeld Str Run Range	6 D AWG-4 A AWG
Conductor - CopperWeld Str Run	• 6 D AWG • 5 A AWG • 5 D AWG • 5 P AWG • 4 A AWG
Conductor Type	• CU C Solid-Run • CU C Str-Run • CU Weld C Solid-Run • CU Weld C Str-Run • CU C Str-Tap • CU Weld C Solid-Tap • CU Weld C Str-Tap
Conductor - Copper Str Tap Range	6 STR - 3 STR
Conductor - Copper Str Tap	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	34 mm
Width	0.6 in

Dimension - Width mm	21 mm
Dimension - Width inch	0.84 in
Dimension - Cross Flats inch	.74 in
Dimension - Length Overall inch	1.5

Force Related

Installation Torque Recommended	275 LBS/in
in-lb	

General

Product Family	Power Connectors>Split Bolts>KS
Trade Name	SERVIT®
Plated	No
Sub Brand	SERVIT
Product Type	Mechanical



A Hubbell brand

UPC	781810022504
Type	KS-3, Compact
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810022504
UPC 14 Digit GTIN	00781810022504

Logistics

Minimum Pack Quantity	1
Pallet Quantity	17400
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)