



KS22NK, Split Bolt Connector, Run: #6-#2 AWG, Tap: #14-#2 AWG, Nickel Plated

By Burndy
Catalog # [KS22NK](#)

Cu Alloy SERVIT Split Bolt, #6 - #2 AWG(Run), #14 - #2 AWG(Tap), Nickel Plated

Features


- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL486D
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Industry Standard(s)	UL486D
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	6 STR - 3 STR
Conductor - Copper Solid Run	2 AWG
Conductor - Copper Solid Tap	2 AWG
Conductor Type	• CU C Solid-Run • CU C Str-Run • CU Weld C Str-Run • CU C Solid-Tap

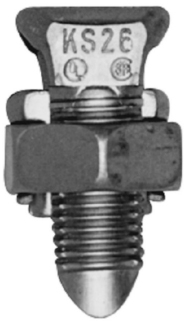

- CU C Str-Tap
 - CU Weld C Str-Tap
- 6 STR - 3 STR

Conductor - Copper Str Tap Range

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Width	0.6 in
Dimension - Length Overall	1.5 inch

General

Plated	Y
Trade Name	SERVIT®
UPC	781810092811
Material	Copper
Plating Type	Nickel
UPC 12 Digit	781810092811
UPC 14 Digit GTIN	00781810092811

Logistics

Pallet Quantity	17400
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)