


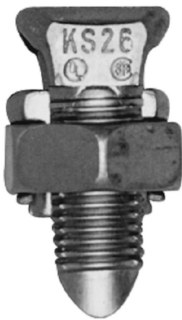

KS22TN, Split Bolt Connector, Run: #6-#2 AWG, Tap: #14-#2 AWG, Tin Plated

By Burndy
Catalog # [KS22TN](#)

Cu Alloy SERVIT Split Bolt, #6 - #2 AWG(Run), #14 - #2 AWG(Tap), Tin Plated



Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL486D
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Industry Standard(s)	UL486D
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	6 STR - 3 STR
Conductor - Copper Solid Run	2 AWG
Conductor - Copper Solid Tap	2 AWG
Conductor Type	• CU C Solid-Run • CU C Str-Run • CU Weld C Str-Run • CU C Solid-Tap • CU C Str-Tap

Conductor - Copper Str Tap Range	• CU Weld C Str-Tap 6 STR - 3 STR
----------------------------------	---

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Width	0.6 in
Dimension - Length Overall	1.5 inch

General

Plated	Y
Trade Name	SERVIT®
UPC	781810094129
Material	Copper
Plating Type	Tin Plated
UPC 12 Digit	781810094129
UPC 14 Digit GTIN	00781810094129

Logistics

Minimum Pack Quantity	100
Pallet Quantity	46400
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)