


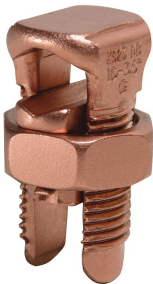

KS25TN, Split Bolt Connector, Run: #4-1/0 AWG, Tap: #14-1/0 AWG, Tin Plated

By Burndy
Catalog # [KS25TN](#)

Cu Alloy SERVIT Split Bolt, #4 - 1/0 (Run), #14 - 1/0 AWG(Tap),
Tin Plated



Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Specifications

Standards - Industry Standards	• UL 486A
Met	• UL486B
Standards - RoHS Compliance	CM
Status	
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	• UL 486A • UL486B

Conductor

Conductor - Copper Str Run Range	4 STR - 1/0 STR
Conductor - Copper Solid Run	2/0 AWG
Conductor - Copper Solid Tap	2/0 AWG
Conductor Type	• CU C Solid-Run • CU C Str-Run • CU Weld C Solid-Run • CU Weld C Str-Run • CU C Str-Tap • CU Weld C Solid-Tap • CU Weld C Str-Tap • CU C Solid-Tap
Conductor - Copper Str Tap Range	4 STR - 1/0 STR

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Dimension - Width mm	19 mm
Dimension - Width inch	0.73 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	45 mm
Width	0.73 in
Dimension - Cross Flats inch	.94 in
Dimension - Width fraction	73/100 in
Dimension - Length Overall inch	1.77

Force Related

Installation Torque	385 in
Recommended in-lb	

General

Plated	Y
Trade Name	SERVIT®
UPC	781810349243
Material	Copper
Plating Type	Tin Plated
UPC 12 Digit	781810349243
UPC 14 Digit GTIN	00781810349243

Logistics

Minimum Pack Quantity	1
Pallet Quantity	14850
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)